


iOnex® 16 Pin USB Type-C

USB4105

- ⚡ Cost-effective 16-pin design
- ⚡ 5 Amp charging capability
- ⚡ Hybrid mount type Through-Hole shell stakes, SMT contacts

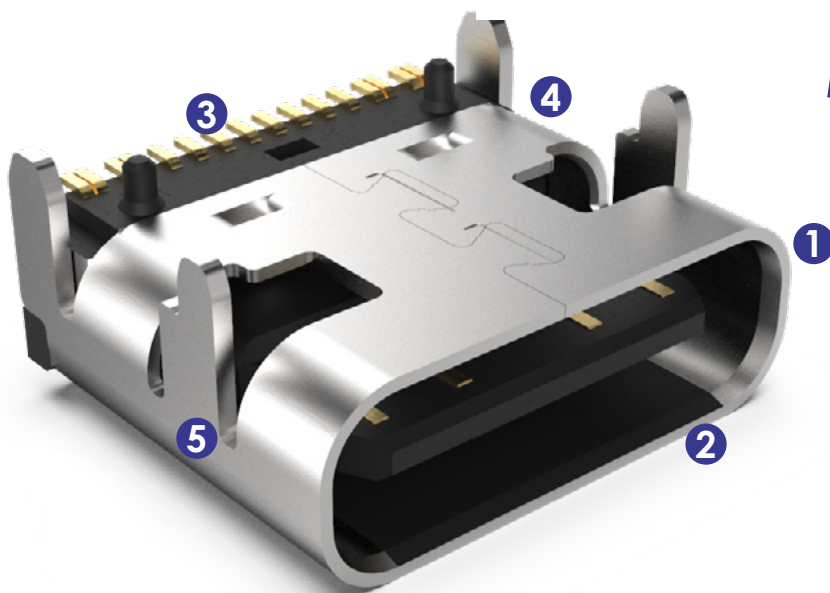

Vital Stats

Interface	Current Rating
USB C	5 Amps
No. of Contacts	Mating Cycles
16	10,000
USB Specification	Profile Above PCB
2.0	3.31mm

- 1 Horizontally mounted socket
- 2 USB C interface
- 3 16 contact USB 2.0 specification
- 4 4 through-hole shell stakes
- 5 Stainless steel shell

Applications

In-Vehicle Entertainment
Portable Electronics
Satellite Navigation
Home Security
Audio Equipment



GCT

gct.co/connector/usb4105