


ionex® 6 Pin USB Type-C

Power-only USB4125

- ⚡ Cost-effective 6-pin design
- ⚡ True power only USB-C configuration
- ⚡ Double the standard mating cycles for USB-C

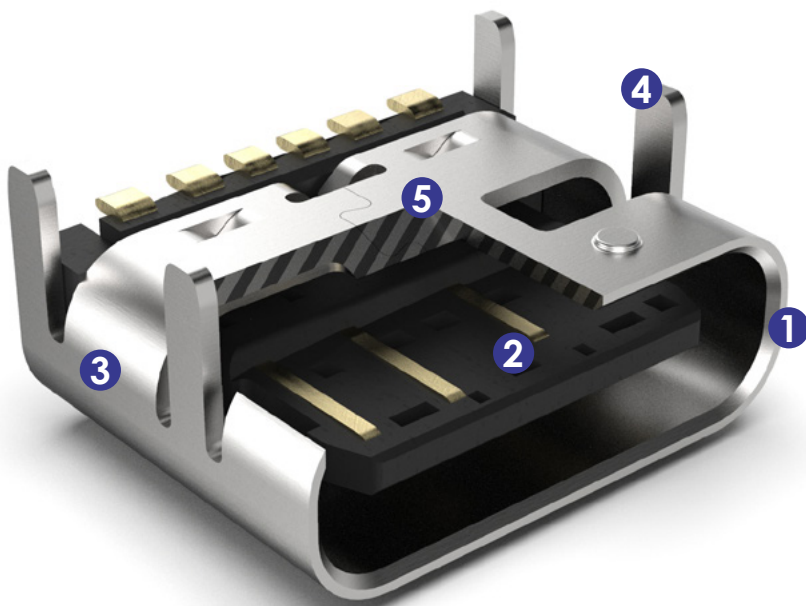

Vital Stats

Interface	Current Rating
USB C	3 Amps
No. of Contacts	Mating Cycles
6	20,000
USB Specification	Profile Above PCB
Power Only	3.16mm

- 1 Horizontally mounted socket
- 2 USB C interface with 6 contacts
- 3 Low profile above PCB
- 4 4 through-hole shell stakes
- 5 Compact PCB Footprint

Applications

Electronic Signage
Dental Equipment
Satellite Navigation
Breathalyzers
Audio Equipment



gct.co/connector/usb4125