




Bumpon™ Protective Products and Rollstock

Use as Feet, Stops, Spacers, Protectors



Standard Molded Shapes

	product	color	adhesive	width		height		hardness Shore A
				inches	mm	inches	mm	
Transparent	1 SJ5382	c	A-20	0.250	6.4	0.075	1.9	75
	2 SJ5302	c	A-20	0.312	7.9	0.085	2.2	75
	3 SJ5306	c	A-20	0.375	9.5	0.150	3.8	75
	4 SJ5303	c	A-20	0.440	11.2	0.200	5.1	75
	5 SJ5312	c	A-20	0.500	12.7	0.140	3.6	75
Quiet Clear	6 SJ6506	c	R-25	0.375	9.5	0.150	3.8	55
	7 SJ6553	c	R-25	0.433	11.0	0.120	3.1	55
	8 SJ6561	c	R-25	0.433	11.0	0.150	3.8	55
	9 SJ6512	c	R-25	0.500	12.7	0.140	3.5	55
Hemisphere	10 SJ5003	w,g,b	R-30	0.440	11.2	0.200	5.1	70
	11 SJ5027	w,g,b	R-30	0.630	16.0	0.312	7.9	70
	12 SJ5017	w,g,b	R-30	0.750	19.1	0.380	9.7	70
	13 SJ5009	w,g,b	R-30	0.880	22.4	0.400	10.2	70
Cylindrical	14 SJ5532*	g,b	R-30	1.880	47.8	0.660	16.8	70
	15 SJ5076	b	R-30	0.315	8.0	0.110	2.8	70
	16 SJ5012	w,g,br,b	R-30	0.500	12.7	0.140	3.6	70
	17 SJ5001	b	R-30	0.500	12.7	0.145	3.6	70
	18 SJ5744	b	R-30	0.750	19.1	0.160	4.1	70
Square	19 SJ5007	b,w	R-30	0.413	10.4	0.098	2.5	70
	20 SJ5008	w,g,b	R-30	0.500	12.7	0.120	3.0	70
	21 SJ5018	w,g,br,b	R-30	0.500	12.7	0.230	5.8	70
	22 SJ5023	w,g,br,b	R-30	0.812	20.6	0.300	7.6	70
	23 SJ5514	w,g,br,b	R-30	0.812	20.6	0.520	13.2	70
	24 SJ5307	c	A-20	0.413	10.4	0.098	2.5	75
Hexagon	25 SJ5705	b	R-30	1.280	32.4	0.250	6.4	70
	26 SJ5202	lbr	R-25	0.433	11.0	0.063	1.6	25
	27 SJ5201	lbr	R-25	0.433	11.0	0.125	3.2	25

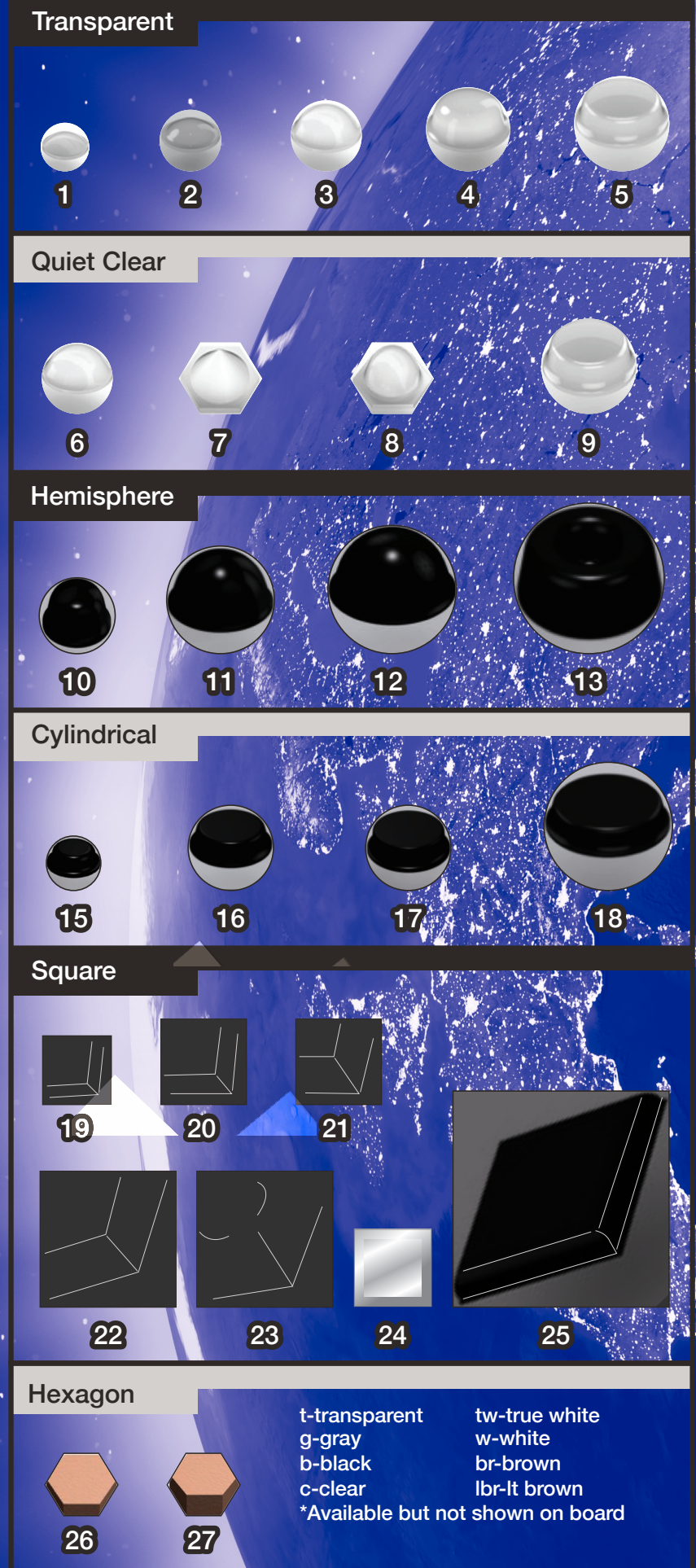

Resilient Rollstock

product	color	adhesive	thickness mm	hardness Shore A
28 SJ56xx	c	A-20	1.6 0.8	75
29 SJ59xx	b	A-20	6.4 3.2 1.6	36
30 SJ52xx	lbr	R-25	3.2 1.6	40
31 SJ58xx/60xx/62xx	b, br	R-30/A-20/R-25	3.2 1.6 0.8	72



Electronics Markets Solutions Division
3M Center, 224-3N-13
St. Paul, MN 55144-1000

1 800 362 3550
www.3M.com/bumpon

"Bumpon" is a registered trademark of 3M.
©2014, 3M. All rights reserved.
70-0064-6071-4

