




MALLORY SONALERT PRODUCTS, INC.

Technical Bulletin No. 06-10

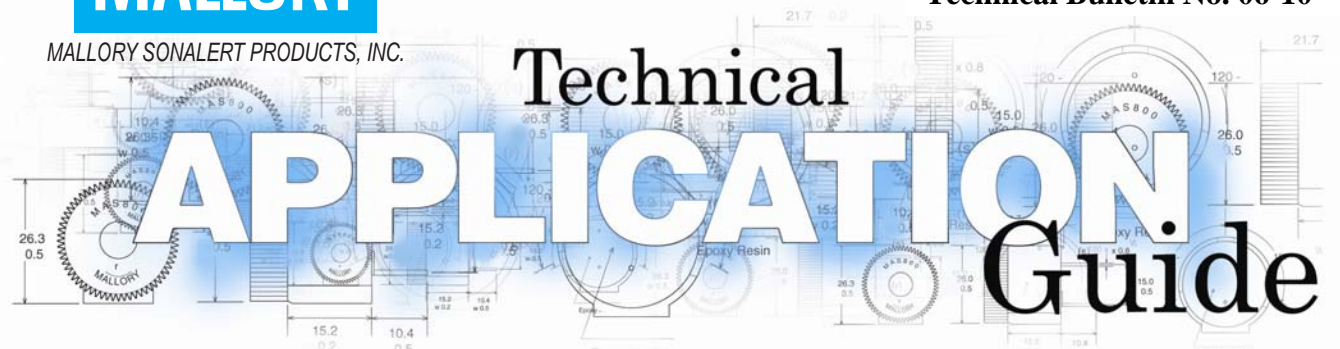

# Technical APPLICATION Guide

## Part Numbering System SC, LSC, SBM, SNP, & VSB Series

Part Number Structure SC    648A    NP    R

Series

SC = Screw Neck Panel Mount	LSC = LED Alarm
SBM = Large Board Mount	SNP = Snap-in Mount
VSB = Specialty Sound	

Voltage Range & Type

307 = 3 to 7 Vdc	616 = 6 to 16 Vdc	628 = 6 to 28 Vdc
628A = 6 to 28 Vac/dc	648 = 10 to 48 Vdc	648A = 10 to 48 Vac/dc
110 = 30 to 120 Vac/dc	250 = 60 to 250 Vac/dc	

Suffixes

CP = Chime	D = 1900 Hz	E = Soft / 1900 Hz	F = Soft
H = 4500 Hz	J = Slow Pulse	K = Short Pulse	L = Lead Wires
M = Military	N = Loud	P = Fast Pulse	PU = Dual Mode
Q = Chirp	S = Siren	W = Warble	WY/WXY = Multi Sound

RoHS: R = RoHS Compliant

Note:

If there are any questions on the part number, you can download the data sheet for the alarm at: [www.mallory-sonalert.com](http://www.mallory-sonalert.com) or you can call for assistance at 317-612-1000.