



▲ Portable Electrocardiograph



▲ Blood Glucose Meter and more...

## RF Switch



### MS-180

RF Switch for Module  
Functionality Inspection  
Height: 0.85mm  
Frequency: 11GHz Max.  
Characteristic Impedance: 50Ω

## Micro USB



### CX


USB Type-C Connector  
USB4 Gen.2×2

## Micro Coaxial



### U.FL

Mated Height: 1.9-2.4mm  
Applicable Cable:  
ø0.81/0.95/1.13/  
1.32/1.37mm

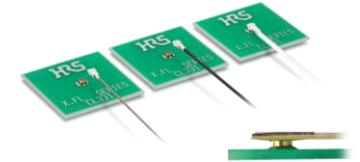

### X.FL


Mated Height: 0.94-1.2mm  
Applicable Cable:  
ø0.5/0.64/0.81/1.13mm

## Low Profile Stacking



### BM25

Pitch: 0.4mm  
Mated Height: 0.7mm  
Depth: 2.6mm  
No. of Pos.: 2(Power)  
4(Signal)  
Rated Current: 10A (Power)  
0.3A(Signal)

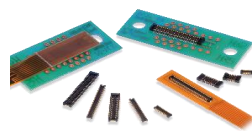

### DF37

Pitch: 0.4mm  
Mated Height:  
0.98-1.5mm  
Depth: 2.98mm  
No. of Pos.: 10-70  
Rated Current: 0.3A

## FPC/FFC



### FH34 FH™

Top/Bottom Contact  
Back Flip  
Pitch: 0.5mm  
Height: 1.0mm  
Depth: 3.8mm  
No. of Pos.: 4-50  
Rated Current: 0.5A



### FH72 OneAction FH™

Top Contact  
One Action  
Pitch: 0.3mm  
Height: 0.9mm  
Depth: 3.5mm  
No. of Pos.: 11-31  
Rated Current: 0.3A



### FH58 FH™

Top/Bottom Contact  
Pitch: 0.2/0.25mm  
Height: 0.9mm  
Depth: 3.1mm  
No. of Pos.: 7-81  
Rated Current: 0.2A