

Brand & Product Introduction

Power Life Better





Table of Contents

P.02	PD Charger Premium
P.08	PD Charger
P.10	Laptop Charger Professional
P.14	Laptop Charger
P.20	Battery Pack Station
P.22	Battery Pack On-The-Go
P.26	Cable & Others
P.32	Brand Introduction

PD Charger Premium Series

Innergia PD Charger Premium Series features a minimalist and compact design that integrates advanced power technology, delivering a smart, stable, and fast charging experience. With an interchangeable design and built-in safety features, the series ensures seamless adaptability in 150+ countries.

Ranging from 30W to 100W and beyond, it meets diverse charging needs for daily life, entertainment, business, and professional use.



45W Premium Dual USB-C PD Charger

3 Years Warranty

Port	Dual USB-C
Wattage	1 Port : Up to 45W 2 Ports : 30W↔15W / 20W+20W
AC Input	100.0-240.0V AC / 1.3A 50-60 Hz
DC Output	5.0V=3.0A ; 9.0V=3.0A ; 12.0V=3.0A ; 15.0V=3.0A ; 20.0V=2.25A ; PPS 5.0V-16.0V=3.0A
Size	45.6x42.8x30.4mm / 95g, 59cc
Charging Protocol	PD3.0 (PPS) / QC3.0 / QC4 / SFC1.0 / Apple Mode
Plug Options	Foldable / Interchangeable*



30W Premium Dual USB-C PD Charger

3 Years Warranty

Port	Dual USB-C
Wattage	1 Port : Up to 30W 2 Ports : Up to 15W per port, 24 max
AC Input	100.0-240.0V AC / 1.0A 50-60 Hz
DC Output	5.0V=3.0A ; 9.0V=3.0A ; 12.0V=2.5A 15.0V=2.0A ; 20.0V=1.5A
Size	45.6x42.8x30.4mm / 70.5g, 59cc
Charging Protocol	PD3.0 / QC3.0 / QC4 / Apple Mode
Plug Options	Foldable / Interchangeable*



*Compatible with [World Travel Plug Kit](#) for interchangeable plug options.
- Check P.33 for details -

*Compatible with [World Travel Plug Kit](#) for interchangeable plug options.
- Check P.33 for details -



60W Premium USB-C PD Charger

3 Years Warranty

Port	Single USB-C
Wattage	Up to 60W
AC Input	100.0-240.0V AC / 1.6A 50-60 Hz
DC Output	5.0V=3.0A ; 9.0V=3.0A ; 12.0V=3.0A 15.0V=3.0A ; 20.0V=3.0A
Size	60x30.4x30.4mm / 89g, 55cc
Charging Protocol	PD3.0 / Apple Mode
Plug Options	Foldable / Interchangeable*



67W Premium Dual USB-C PD Charger

3 Years Warranty

Port	Dual USB-C
Wattage	1 Port : Up to 67W 2 Ports : 45W+20W / 30W+30W
AC Input	100.0-240.0V AC / 1.7A 50-60 Hz
DC Output	5.0V=3.0A ; 9.0V=3.0A ; 12.0V=3.0A ; 15.0V=3.0A ; 20.0V=3.35A ; PPS 5.0V-16.0V=3.0A
Size	56x47x30.4mm / 135g, 80cc
Charging Protocol	PD3.0 (PPS) / QC5 / SFC1.0 / Apple Mode
Plug Options	Foldable / Interchangeable*

60W & 67W : Classic Speed, Professional Power.

Reliable and efficient charging for most business laptops, with smart power allocation that seamlessly adapts to lower-power devices like tablets, smartphones, and earbuds.

*Compatible with [World Travel Plug Kit](#) for interchangeable plug options.
- Check P.33 for details -





100W Premium USB-C PD Charger

3 Years Warranty

Port	Single USB-C
Wattage	Up to 100W
AC Input	100.0-240.0V AC / 1.7A 50-60 Hz
DC Output	5.0V=3.0A ; 9.0V=3.0A ; 12.0V=3.0A ; 15.0V=3.0A ; 20.0V=5.0A ; PPS 5.0V-21.0V=5.0A
Size	54x53x30.4mm / 163g, 87cc
Charging Protocol	PD3.0 (PPS) / QC4 / SFC2.0 / Apple Mode
Plug Options	Foldable

World Travel Plug Kit

Fast Charge in 150+ Countries

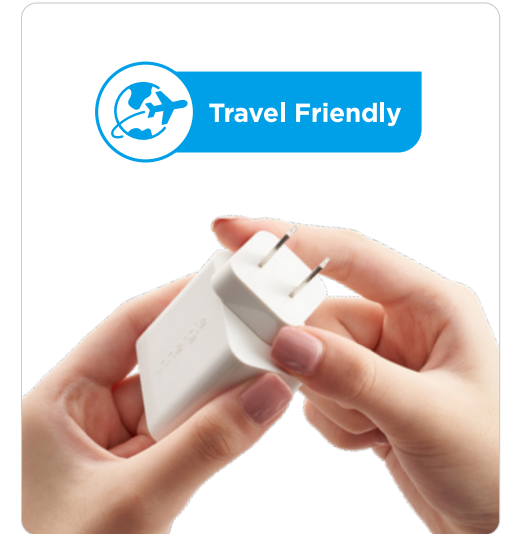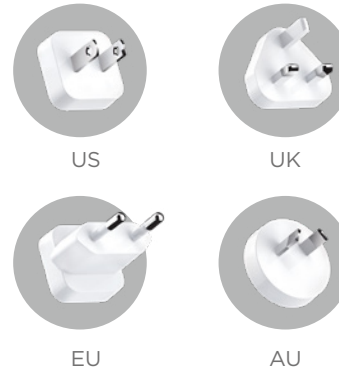

100W Premium Dual USB-C PD Charger

3 Years Warranty

Port	Dual USB-C
Wattage	1 Port : Up to 100W 2 Ports : 65W↔30W / 45W+45W
AC Input	100.0-240.0V AC / 1.7A 50-60 Hz
DC Output	5.0V=3.0A ; 9.0V=3.0A ; 12.0V=3.0A ; 15.0V=3.0A ; 20.0V=3.0A ; PPS 5.0V-21.0V=3.0A
Size	67x56x30.4 mm / 230g, 114cc
Charging Protocol	PD3.0 (PPS) / QC5 / SFC1.0 / Apple Mode
Plug Options	Foldable / Interchangeable*



*Compatible with [World Travel Plug Kit](#) for interchangeable plug options.
- Check P.33 for details -

PD Charger

The Innergia PD Charger Series delivers reliable, high-speed charging in a compact, minimalist design. Built with essential power technology and universal USB-C compatibility, it's a dependable solution for everyday charging—at home, at work, or on the go.

Designed for users who value both performance and portability, the PD Charger Series offers the perfect balance of efficiency, safety, and simplicity.



Product ID : ADP-65YW

65W Dual USB-C PD Charger

3 Years Warranty

Port	Dual USB-C
Wattage	C1 : Up to 65W / C2 : Up to 27W C1+C2 : 45W+20W
AC Input	100.0-240.0V AC / 1.6A 50-60 Hz
DC Output	C1 : 5.0V=3.0A ; 9.0V=3.0A ; 12.0V=3.0A ; 15.0V=3.0A ; 20.0V=3.25A ; PPS 5.0V-11.0V=5.0A ; PPS 5.0V-21.0V=3.25A C2 : 5.0V=3.0A ; 9.0V=3.0A ; PPS 5.0V-11.0V=3.0A
Size	54x53x30.4 mm / 150g, 87cc
Charging Protocol	PD3.0 (PPS) / QC4 / SFC1.0 SFC2.0 / AFC
Plug Options	UK*



Product ID : ADP-30PW

30W USB-C PD Charger

3 Years Warranty

Port	Single USB-C
Wattage	Up to 30W
AC Input	100.0-240.0V AC / 1.0A 50-60 Hz
DC Input	5.0V=3.0A ; 9.0V=3.0A ; 12.0V=2.5A ; 15.0V=2.0A ; 20.0V=1.5A ; PPS 5.0V-11.0V=4.5A ;
Size	32x32x37mm / 65g, 38cc
Charging Protocol	PD3.0 (PPS) / QC4+ / SFC1.0 / SFC2.0
Plug Options	US / UK / EU*



Product ID : ADP-70PW

70W USB-C PD Charger

3 Years Warranty

Port	Single USB-C
Wattage	Up to 70W
AC Input	100.0-240.0V AC / 1.0A 50-60 Hz
DC Output	5.0V=3.0A ; 9.0V=3.0A ; 2.0V=3.0A ; 15.0V=3.0A ; 20.0V=3.5A ; PPS 5.0V-11.0V=4.5A (Max) PPS 5.0V-21.0V=3.0A (Max)
Size	54x28.4x30.4mm / 95g, 47cc
Charging Protocol	PD3.0 (PPS) / QC4+ / SFC1.0 / SFC2.0
Plug Options	US*

*US : United States / UK : United Kingdom / EU : European Union

*US : United States / UK : United Kingdom / EU : European Union

6 Tips



180W Tip Professional Laptop Charger

Tip Service 3 Years Warranty

Variations	6 Tips
Output Power	Up to 180W
AC Input	100.0-240.0V AC / 2.3A 50-60 Hz
DC Input	19.5V=9.23A
Size	152x72.5x22.5mm / 415g, 248cc
Usage Type	Desk

Inside the Box

- Power Adapter with 1.8m Built-in cable
- 1m AC Cable
- 6 Tips*

Product ID : ADP-180TB

*6 Tips are compatible with most gaming laptop brands :
Acer, ASUS, ROG, Alienware, Dell, HP, Lenovo, MSI

Laptop Charger Professional Series

The Innergie Laptop Charger Professional Series showcases Delta Electronics' 50+ years of expertise in power supply. Designed for creative professionals and gaming enthusiasts, it delivers a stable, safe, and high-performance charging experience for high-powered laptops.

Ranging from 140W to 330W, the series combines traditional tips with USB-C PD technology, offering Pro users a versatile range of options to power their work and passion.

240W Tip Professional Laptop Charger

Tip Service 3 Years Warranty

Variations	5 Tips
Output Power	Up to 240W
AC Input	100.0-240.0V AC / 3.5A 50-60Hz
DC Input	20.0V=12.0A
Size	165x76x25.4mm / 570g, 318cc
Usage Type	Desk

Inside the Box

- Power Adapter with 1.2m Built-in cable
- 1m AC Cable
- 5 Tips**

Product ID : ADP-240EB

**5 Tips are compatible with most gaming laptop brands :
Acer, ASUS, ROG, Alienware, Dell, HP, Lenovo, MSI

5 Tips



Gt

Acer

Dt

Lenovo



F1t

HP
MSI

Xt

ASUS /
ROG

Ct

Dell /
Alienware

330W Tip Professional Laptop Charger

Tip Service

3 Years Warranty



Product ID : ADP-330GB

Variations	5 Tips
Output Power	Up to 330W
AC Input	100.0-240.0V AC / 4.5A 50-60Hz
DC Input	19.5V=16.9A
Size	185x85x31mm / 844g, 488cc
Usage Type	Desk
Inside the Box	<ul style="list-style-type: none"> · Power Adapter with 1.8m Built-in cable · 1m AC Cable · 5 Tips*

280W Tip Professional Laptop Charger

Tip Service

3 Years Warranty



Product ID : ADP-280DB

Variations	5 Tips
Output Power	Up to 280W
AC Input	100.0-240.0V AC / 4.4A 50-60Hz
DC Input	19.5V=14.36A
Size	200x100x25.4mm / 840g, 508cc
Usage Type	Desk
Inside the Box	<ul style="list-style-type: none"> · Power Adapter with 1.8m Built-in cable · 1m AC Cable · 5 Tips*

*5 Tips are compatible with most gaming laptop brands :
Acer, ASUS, ROG, Alienware, Dell, HP, Lenovo, MSI



Laptop Charger

The Innergie Laptop Charger Series offers versatile, reliable charging for a wide range of laptops and devices. Designed with essential power technology, it supports both traditional tip types and USB-C output, covering power needs from 45W to 100W. Delivering the same quality as an original laptop charger, this series is a dependable backup solution for office users, students, and everyday laptop users.



65W Tip Laptop Charger

Tip Service

3 Years Warranty

Variations	3 Tips / 6 Tips / +C-Converter
Output Power	Up to 65W
AC Input	100.0-240.0V AC / 1.5A 50-60Hz
DC Input	19.0V=3.42A
Size	63x63x28.5mm / 202g, 113cc
Usage Type	Wall
Inside the Box	· Power Adapter with 2.3m Built-in cable · See Variations

Variations :

6 Tips



D1
Lenovo



F1
HP
MSI



G
Acer



L
Acer



M
Dell



N
Asus

C-Converter



3 Tips

Acer



A



G



L

Asus



A



K



N

Dell



A



C



M

HP



B



F



F1

Lenovo



A



D1



I



Product ID : ADP-90NE

90W Tip Laptop Charger

Tip Service

3 Years Warranty

Variations	3 Tips / 6 Tips
Output Power	Up to 90W
AC Input	110.0-240.0V AC / 1.5A 50-60Hz
DC Input	19.0V=4.74A
Size	74.8x74.8x29mm / 225g, 162cc
Usage Type	Wall
Inside the Box	<ul style="list-style-type: none"> Power Adapter with 1.5m Built-in cable See Variations

Variations :



6 Tips



D1
Lenovo



F1
HP
MSI



G
Acer



L
Acer



M
Dell



N
Asus



3 Tips

Dell



A



C



M

HP




B




F



F1

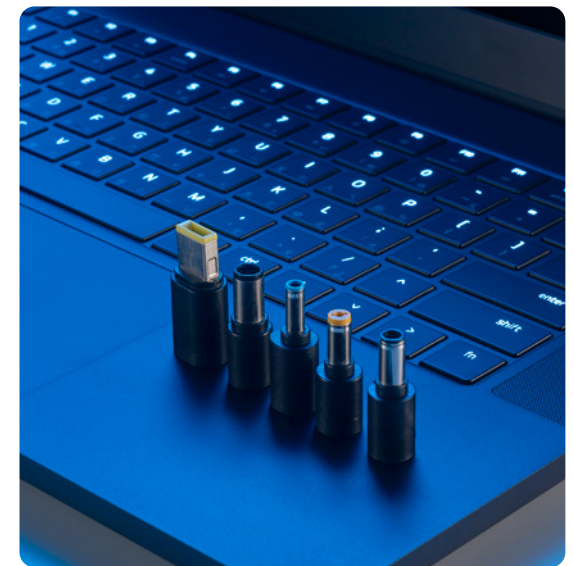

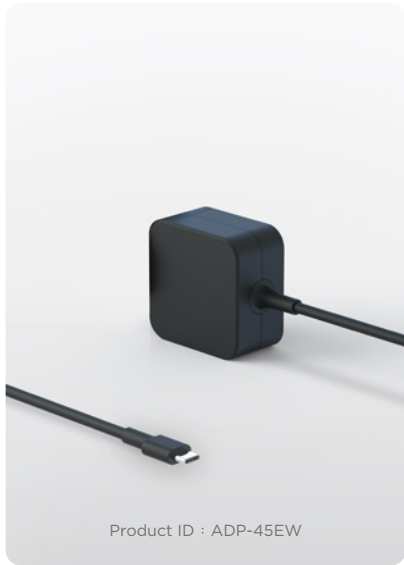

45W USB-C Laptop Charger

3 Years Warranty

Port	Single USB-C
Output Power	Up to 45W
AC Input	100.0-240.0V AC / 1.2A 50-60Hz
DC Input	5.0V=3.0A ; 9.0V=3.0A ; 15.0V=3.0A ; 20V=2.25A
Size	53x53x28.5mm / 200g, 80cc
Built in Cable	2m
Usage Type	Wall



65W USB-C Laptop Charger

3 Years Warranty

Port	Single USB-C
Output Power	Up to 65W
AC Input	100.0-240.0V AC / 1.5A 50-60Hz
DC Input	5.0V=3.0A ; 9.0V=3.0A ; 15.0V=3.0A ; 20V=3.25A
Size	63x63x28.5mm / 220g, 113cc
Built in Cable	2m
Usage Type	Wall



100W USB-C Laptop Charger

3 Years Warranty

Port	Single USB-C
Output Power	Up to 100W
AC Input	100.0-240.0V AC / 1.2A 50-60Hz
DC Input	5.0V=3.0A ; 9.0V=3.0A ; 15.0V=3.0A ; 20V=5.0A
Size	75x75x29mm / 290g, 163cc
Built in Cable	1.5m
Usage Type	Desk

Battery Pack Station Series


The Innergie Battery Pack Station Series is a modular, app-controlled power solution designed for flexible group use. Ideal for shared workspaces, meetings, events, outdoor activities, and emergency backup, it delivers reliable power wherever it's needed.

Its detachable design separates the battery from the dock, enabling quick and easy deployment across different scenarios. A six-slot charging base allows fast, simultaneous charging of multiple battery units—perfect for team-based or rotational use.

Available in two capacities—200Wh and 400Wh—each unit delivers up to 195W of total PD fast charging, supporting laptops, tablets, smartphones, and more.



APP
BT



Product ID : BEA200B120DZ-AA

200W 195W Mobile Power Station

1 Year Warranty

Port	Four USB-C
Wattage	Up to 195W
Capacity	200Wh / 11,600mAh (18.15V)
Max Input	C1 : Up to 60W
Max Output	C1 : Up to 60W / C2, 3, 4 : Up to 45W
Size	125x110x233.5 mm / 310g
Charging Protocol	PD3.0 (PPS) / QC3.0 / Apple 2.4A / Samsung AFC
Charging Time	2.5hr (0-80%) / 4hr (0-100%)

APP
BT



Product ID : BEA400B120DZ-AA

400W 195W Mobile Power Station

1 Year Warranty

Port	Four USB-C
Wattage	Up to 195W
Capacity	400Wh / 23,200mAh (18.15V)
Max Input	C1 : Up to 60W
Max Output	C1 : Up to 60W / C2, 3, 4 : Up to 45W
Size	125x110x273 mm / 360g
Charging Protocol	PD3.0 (PPS) / QC3.0 / Apple 2.4A / Samsung AFC
Charging Time	5hr (0-80%) / 8hr (0-100%)



5100mAh 20W Magnetic Battery Pack

1 Year Warranty

Port	Single USB-C
Wattage	Wireless : Up to 15W USB-C : Up to 20W (In / Out)
DC Input	5.0V=3.0A ; 9.0V=2.2A ; 12.0V=1.67A
DC Output	5.0V=3.0A ; 9.0V=2.2A ; 12.0V=1.67A
Magnetic	Qi2 - 1100g / Back - 900g
Size	100x68x12.5mm / 145g, 85cc
Charging Protocol	Qi2 / PD3.0 (PPS) / QC3.0 / Samsung AFC / APPLE Mode

Battery Pack On-the-Go Series

The Innergie Battery Pack On-the-Go Series combines PD fast charging, power pass-through technology, and Qi2 wireless charging—engineered for life on the move. Perfect for travel, commuting, and remote work, it keeps your devices powered wherever the day takes you.

Available in 5,100mAh and 10,200mAh capacities—both flight-safe—this series covers everyday mobility needs and beyond. The 10,200mAh model delivers up to 45W output, making it ideal for emergency laptop charging on the go.



10200mAh 45W Magnetic Battery Pack

1 Year Warranty

Port	Dual USB-C
Wattage	Wireless : Up to 15W C1 : Up to 45W (In / Out) C2 : Up to 20W (Out)
DC Input	5.0V=3.0A ; 9.0V=3.0A ; 12.0V=3.0A ; 15.0V=3.0A ; 20.0V=2.25A
DC Output	C1 : 5.0V=3.0A ; 9.0V=3.0A ; 12.0V=3.0A ; 15.0V=3.0A ; 20V=2.25A C2 : 5.0V=3.0A ; 9.0V=2.22A ; 12.0V=1.6A ; 15.0V=1.3A ; 20.0V=1.0A
Magnetic	Qi2 - 1100g / Back - 900g
Size	102x68x17.2mm / 220g, 119cc
Charging Protocol	Qi2 / PD3.0 (PPS) / QC4+ / QC3.0 / Samsung AFC / APPLE Mode






10000mAh 30W Battery Pack

1 Year Warranty

Port	Dual USB-C
Wattage	1 Port : Up to 30W 2 Ports : 12W+12W
DC Input	5.0V≐3.0A ; 9.0V≐3.0A ; 15.0V≐2.0A ; 20V≐1.5A
DC Output	5.0V≐3.0A ; 9.0V≐3.0A ; 15.0V≐2.0A ; 20V≐1.5A
Size	137x64x14mm / 223g, 112cc

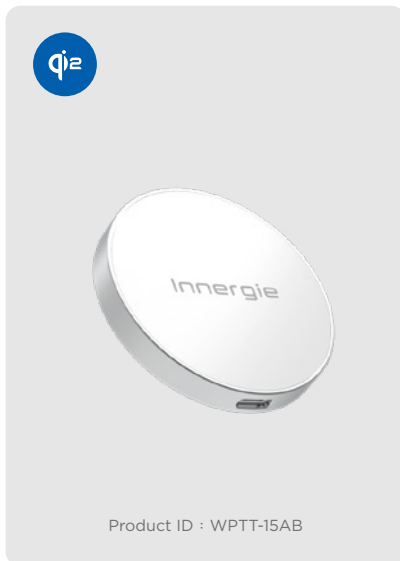

Qi2 15W Magntic Wireless Charger

3 Years Warranty

Port	Single USB-C
Wattage	Up to 15W
DC Input	5V≐2A ; 9V≐3A
USB-C Output	5V≐5W ; 9V≐15W
Magnetic	Qi2 - 600g
Size	60x60x7.77mm / 48g, 21cc
Support	iOS & Android Systems




Qi2 Wireless Charging

Qi2 delivers faster, more efficient charging with magnetic alignment—MagSafe-compatible for precise, secure power every time.

Cable & Others

Innergie's Cable & Others category features essential charging accessories and unique power solutions that seamlessly bridge legacy charging systems into the USB-C era. From high-quality USB-C cables to power converters and travel accessories, each item is designed for durability, compatibility, and everyday convenience.


Whether at home, in the office, or on the move, these accessories complete your charging setup with ease and reliability.

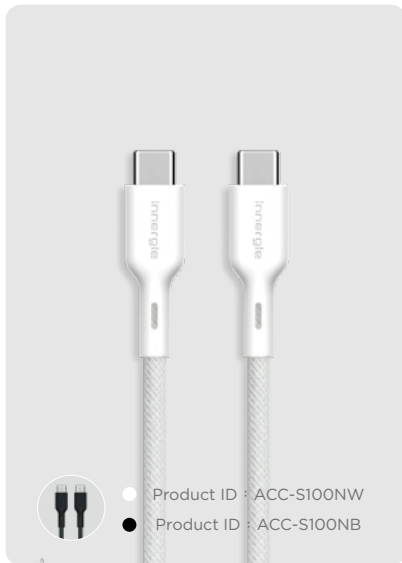

USB-C to USB-C 1M 100W Braided Cable

3 Years Warranty

Fast Charging	5A E-Marker PD 100W
Compatibility	With most USB-C devices. MacBook, iPad, Chromebook, etc.
Support	480 Mbps data sync
Bend Test	25,000+

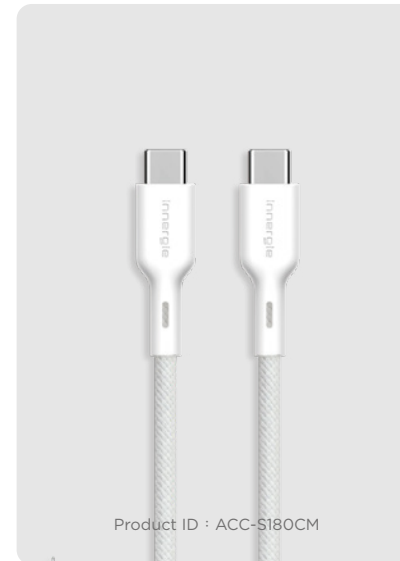

USB-C to USB-C 1.8M 100W Braided Cable

3 Years Warranty


Fast Charging	5A E-Marker PD 100W
Compatibility	With most USB-C devices. MacBook, iPad, Chromebook, etc.
Support	480 Mbps data sync
Bend Test	25,000+



25,000+
Bending Test




10,000+
Insertion and Withdrawal Test

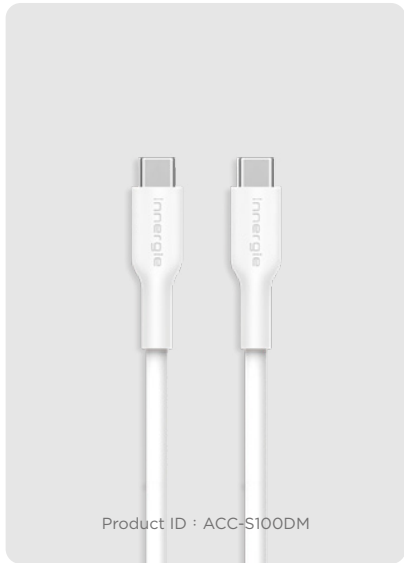

USB-C to USB-C 1M 100W Flex Cable

3 Years Warranty


Fast Charging	5A E-Marker PD 240W
Compatibility	With most USB-C devices. MacBook, iPad, Chromebook, etc.
Support	480 Mbps data sync
Bend Test	25,000+

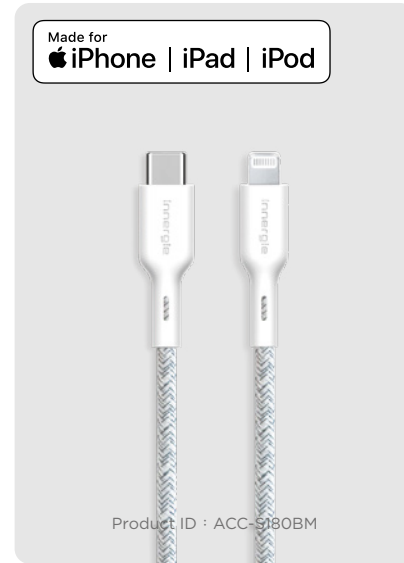

USB-C to Lightning 1.8M 100W Braided Cable

3 Years Warranty

Fast Charging	3A
Compatibility	Perfect Converter for Apple devices. Work with iPhone / iPad etc.
Support	480 Mbps data sync
Bend Test	25,000+

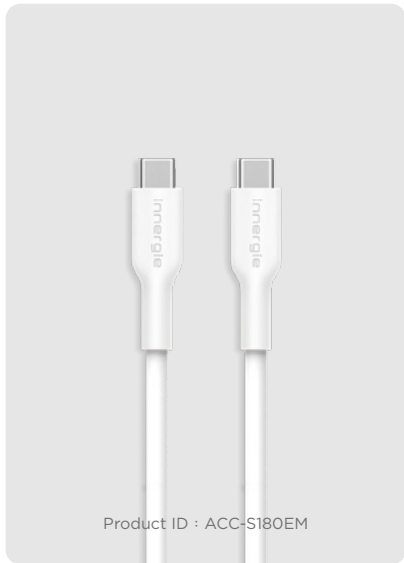

USB-C to USB-C 1.8M 100W Flex Cable

3 Years Warranty

Fast Charging	5A E-Marker PD 240W
Compatibility	With most USB-C devices. MacBook, iPad, Chromebook, etc.
Support	480 Mbps data sync
Bend Test	25,000+

**More Demand ?
Contact Our Sales Window !**



Product ID : ADP-208

World Travel Plug Kit

Plug Rating	2.5A / 250V
Size	US : 29.1x29.1x26mm, 9.3g EU : 29x35.8x47.3mm, 20.7g UK : 48.9x43.7x32.4mm, 20.5g AU : 41x41x27mm, 13.7g
US Plug for	North America, Japan, Thailand, Taiwan
EU Plug for	Continental Europe
UK Plug for	United Kingdom, Singapore, Malaysia
AU Plug for	Australia, New Zealand



C-Converter 3 Years Warranty

Fast Charging	5A PD 100W fast charge
Length	18cm
Size	54x20x16mm, 32g
Support	PD3.0 (PPS) / QC4
Bending Test	25,000+

Compatibility



For HP / ASUS

Tip : 4.5x3mm
Barrel : 12x4.5mm

Product ID :
ADC-100AB



For Acer

Tip : 3x1.1mm
Barrel : 10.5x3mm

Product ID :
ADC-100BB



For Innergie

Tip : 15 (Outer)
Barrel : 15mm

Product ID :
ADC-100CB



To provide new,
clean and energy-efficient solutions for a better future.

Innergie

As part of Delta group, Innergie takes pride of "Power Expert" in a 53 years of power management experience and devotes to push the boundary of power solution with revolutionary technology, making Greener Smarter & Together possible.

A brand of  DELTA



About Delta Group Founded in 1971

World's Leader in Switching Power Supplies and DC Brushless Fans

Dedicated to Providing :

- Telecom Power Systems
- Industrial Automation
- Passive and Magnetic Components
- Networking Products
- Visual Displays
- Datacenter Infrastructure
- Renewable Energy and Energy Storage
- EV Charging Infrastructure





Bruce Cheng

Founder and Honorary Chairman



Yancey Hai

Chairman

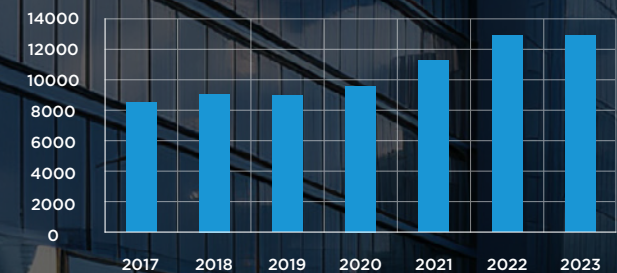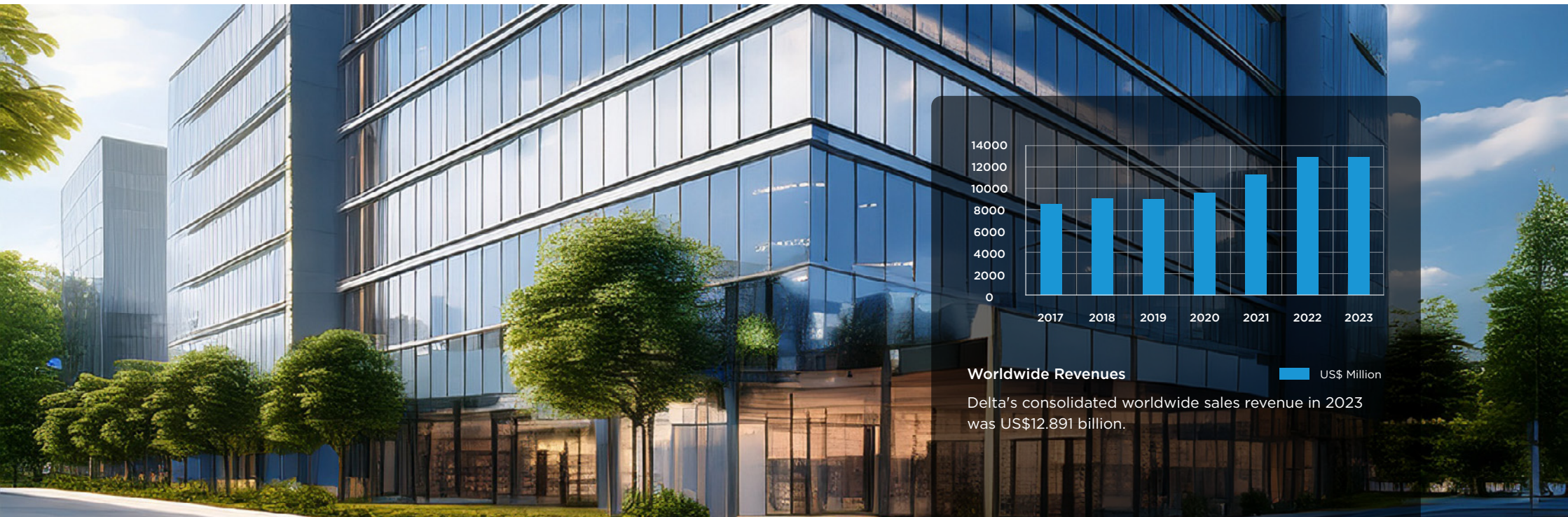

Worldwide Revenues

US\$ Million

Delta's consolidated worldwide sales revenue in 2023 was US\$12.891 billion.



	Asia-Pacific	Americas	EMEA	Total
Sales Offices	100	25	33	158
Plant Sites	40	4	4	48
R&D Centers	48	9	15	72



Every Innergie Charger is produced from **100%** Renewable Electricity.

Every production waste is **100%** Reused & Recycled.
(UL2799 Platinum Rating)
*based on 2021 Delta ESG Report.



Vision

The Greener and Smarter consumer power management brand that enhance people's way of living anytime and anywhere.

Mission

To optimize and enrich the consumer power experience through thoughtful design and smart functionality.

Smaller yet Greener



GreenSense™



2008



Now

1-3 y

Quality Guarantee

Charging experts from the Leading power supply company.

Up to 93 %

High Energy Efficiency

Good Product Efficiency, but can be even Better.

75 %

Recyclable and Reusable

Good Product, should also good for Environment.

Reduce

2.5 tons

Plastic take-away cups

Reduce the use of plastic by more than 2.5 tons a year.

Reduce

50 %

Packaging volume

Up to 50% reduction in packaging volume.

Use

FSC mix

Certified materials

We use FSC MIX certified materials.

The Pioneer of Quality




Warranty




Robust and Stable

Dropping test from 1.5m height in entire, unbeatable.

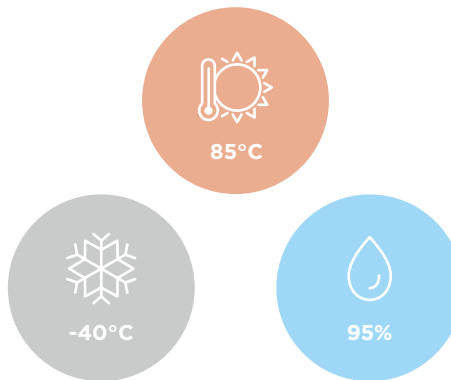

Extreme Temperature Test

Environmental test withstands temperature from 85°C to - 40°C, also 95% humid areas all 168hr long, unbeatable.

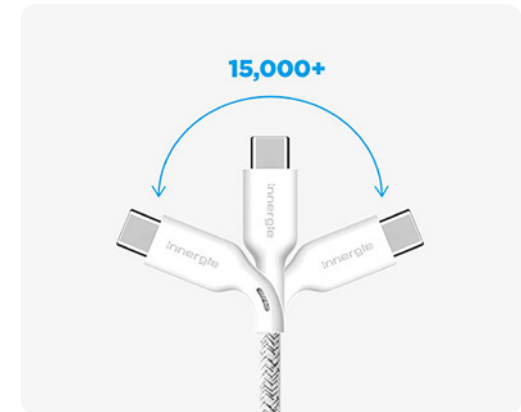

Ultra Durable

15,000+ bend test verified for long-lasting lifespan.

Innovative Design



39 Invention Patents
for making compact & efficient

9 Utility Patents
for making thoughtful usability

38 Design Patents
for making consistent identity