

HRS Integrated Solutions for EV Charger

<Plug-in Type>

<Wireless Type>

Wire-to-Board
(Power)
DF60

Wire-to-Board
(Signal)
DF51/DF51K



Board-to-Board
(Signal)
FX20

Wire-to-Board
(Signal)
DF51/DF51K


Wire-to-Board
(Power)
DF60

Interface
(Power)
HR41A

Interface
(Signal)
LF

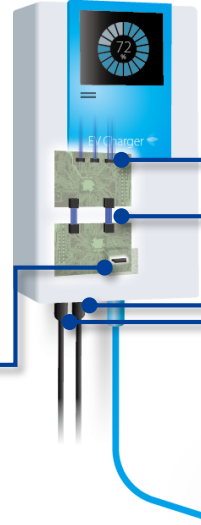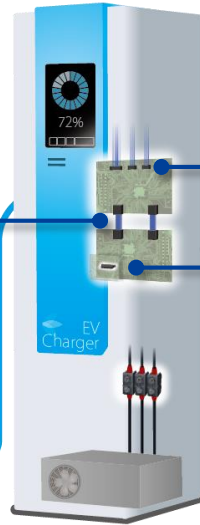

Visit HRS
for More

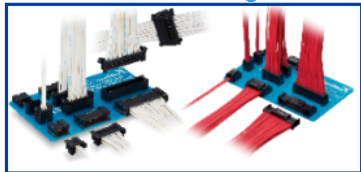


DF51/DF51K Series

2mm Pitch,
Positive Lock,
Wire-to-Board



DF60 Series

65A Max.*Current,
Positive Lock,
Wire-to-Board
*UL Standard

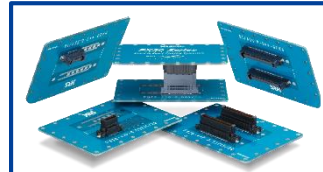

FX20 Series

0.5mm Pitch,
Floating,
Board-to-Board



HR41A Series

IP67/IP68 Waterproof,
Weather-resistant
Connector for Outdoor Use



LF Series

IP67/IP68 Waterproof,
Shielded I/O Connector