




INSULATION DISPLACEMENT CABLE:
0.025" PITCH, 30 AWG, SOLID EXTRUDED FEP

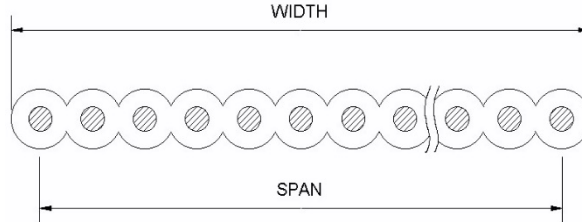

Cond. No.	Part Number	Span	Width
6	1000570267	0.125" ± 0.005"	0.150" ± 0.007"
10	1000570260	0.225" ± 0.005"	0.250" ± 0.007"
16	1000570514	0.375" ± 0.005"	0.400" ± 0.007"
20	1000570261	0.475" ± 0.005"	0.500" ± 0.007"
24	1000570262	0.575" ± 0.005"	0.600" ± 0.007"
26	1000570263	0.625" ± 0.005"	0.650" ± 0.007"
34	1000570264	0.825" ± 0.005"	0.850" ± 0.007"
36	1000570432	0.875" ± 0.005"	0.900" ± 0.007"
40	1000570265	0.975" ± 0.006"	1.000" ± 0.007"
50	1000570266	1.225" ± 0.006"	1.250" ± 0.010"
60	1000570271	1.475" ± 0.006"	1.500" ± 0.010"
68	1000570268	1.675" ± 0.006"	1.700" ± 0.010"
70	1000570269	1.725" ± 0.006"	1.750" ± 0.010"
80	1000570270	1.975" ± 0.006"	2.000" ± 0.010"
100	1000570259	2.475" ± 0.006"	2.500" ± 0.010"

CHARACTERISTICS		
Conductor	30 AWG, Solid, Silver Plated Copper	
Insulation	FEP	
Color	Natural with Blue Polarity Stripe	
Impedance (ohms)	90 Unbalanced	130 Balanced
Capacitance (pF/ft)	14.7 Unbalanced	10.0 Balanced
Inductance (uH/ft)	0.12 Unbalanced	0.17 Balanced
Insulation Resistance (Mohm)	>500	
Voltage Rating	150V	
Temperature Rating	150C	

STANDARD PACKAGING
100 ft./spool, 10 Ft. minimum length

UL STYLE 20726